


PT#: 3 UT#: 1 CPU#: 1

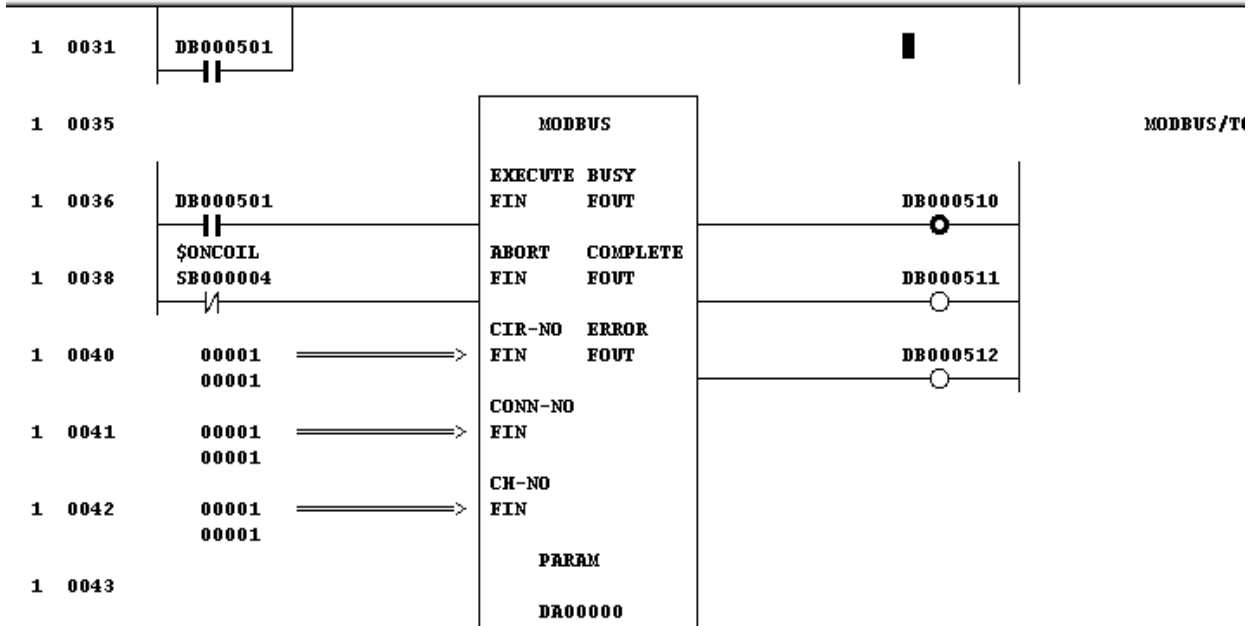

```

Microsoft Windows [Version 4.0.9506]
(c) Copyright 1985-1996 Microsoft Corp.

C:\>PING 192.168.1.200

Pinging 192.168.1.200 with 32 bytes of data:

Reply from 192.168.1.200: bytes=32 time=20ms TTL=15
Reply from 192.168.1.200: bytes=32 time<10ms TTL=15
Reply from 192.168.1.200: bytes=32 time<10ms TTL=15
Reply from 192.168.1.200: bytes=32 time<10ms TTL=15

C:\>
    
```

This indicates the SMC3010 IP address

This indicates the PCs IP address

Register List

File(E) ViewMode(M) Show(Y) Window(W) Help(H)

DEC HEX BIN LONG FLO RT ASC II ?

MP920 ETHTEST\CPU1 MP920 Online Local

PT#: 3 UT#: 1 CPU#: 1

Register No. ML00004 /DWG = /D = 008 /TYPE = LONG Controller

ML00004 = 00012345678	ML00006 = 00000000000	ML00008 = 0000000
ML00012 = 00000000000	ML00014 = 00000000000	ML00016 = 0000000

MP920 ETHTEST\CPU1 MP920 Online Local

PT#: 3 UT#: 1 CPU#: 1

Register No. Mw00000 /DWG = /D = 008 /TYPE = DEC Controller

Mw00000 = 000001	Mw00001 = 000005	Mw00002 = 000069
Mw00004 = 024910	Mw00005 = 000188	Mw00006 = 000000